

DEMAND  
MORE

## Hot water without the wait

Before Grundfos, hot water recirculation solutions were difficult, if not impossible. Now, installations in both new construction and existing homes are quick, easy and profitable.

### Features & Benefits:

- Installations take an hour or less
- In retrofits, the Comfort System bypass valve makes it all possible with no return line and no need for electricity under the sink
- Uses less energy than a 25-watt light bulb (Comfort System Only)
- Can save up to 16,000 gallons of water per year
- Backed by a 30-month warranty
- All products certified to NSF-61 and NSF-372 standards

For more information, go to: [grundfos.us](http://grundfos.us)



### Comfort System

UP 15-10 SU7P TLC  
Pump, valve, line-cord,  
and (2) S.S. flex hoses.



### COMFORT PM AUTO

UP 10-16 A PM BN5/LC  
AUTOADAPT™ and line cord



ANSI/NSF61/372 and IAPMO listed

be  
think  
innovate

GRUNDFOS 

## – Comfort System UP 15-10 SU7P TLC (Part# 595916)

### Pump Technical Data:

Flow, Qmax 6.3 GPM (1.4 m<sup>3</sup>/h)  
 Head, Hmax 5.1 ft (1.6 m)  
 Motor: Single Phase, 115V  
 Min. Fluid Temperature: 36°F (2°C)  
 Max. Fluid Temperature: 150°F (66°C)  
 Max. Working Pressure: 145 PSI

### Electrical Data:


Volts: 1X115V  
 Watts: 25W  
 Amps: 0.23A

**Electrical Connection:** The pump is fitted with a 10ft. line-cord w/plug.

**Timer:** 3 control options available:

- Continuous
- 15-minute intervals
- OFF

### Performance Curve:

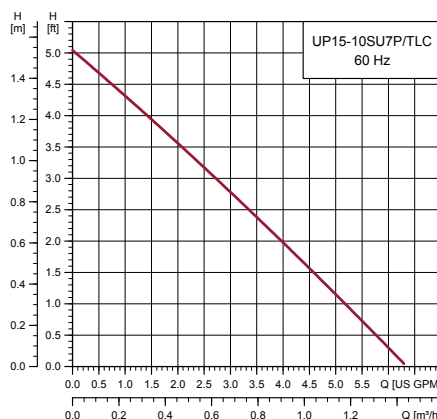

## – COMFORT PM Range


### Pump Technical Data:

Flow, Qmax 2.2 GPM (0.5 m<sup>3</sup>/h)  
 Head, Hmax 3.9 ft (1.2 m)  
 Motor: Single Phase, 115V/208-230V  
 Min. Fluid Temperature: 36°F (2°C)  
 Max. Fluid Temperature: 203°F (95°C)  
 Max. Working Pressure: 145 PSI  
 Standard Features: 6ft. line-cord w/plug

### Electrical Data:

Volts: 1X115V  
 Watts: 5-8.5W  
 Amps: 0.23A

### Performance Curve:

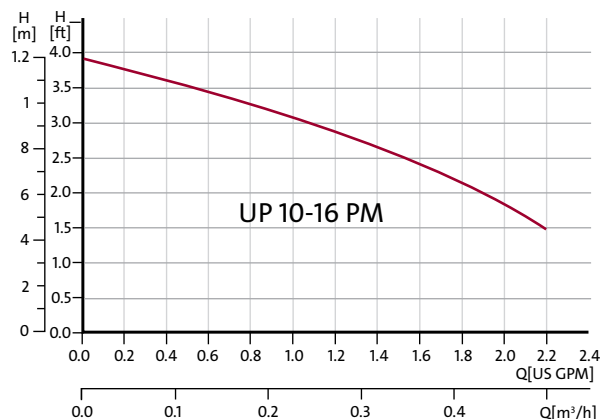

Models	Part Number	1/2" Sweat	1/2" F FNPT	1 1/4" Union	Line Cord	Check Valve	Isolation Valve	AUTO
UP10-16 PM B5/LC	98420206	•			•			
UP10-16 PM BN5/LC	98420210		•		•			
UP10-16 A PM B5/LC	98420222	•			•			•
UP10-16 A PM BN5/LC	98420223		•		•			•
UP10-16 A PM BU/LC	98420224			•	•	•	•	•

L-UP-SL-024 Rev. 08-14

GRUNDFOS Kansas City  
 17100 West 118th Terrace  
 Olathe, Kansas 66061  
 Phone: (913) 227-3400  
 Fax: (913) 227-3500

GRUNDFOS Canada  
 2941 Brighton Road  
 Oakville, Ontario  
 L6H 6C9  
 Phone: (905) 829-9533  
 Fax: (905) 829-9512

GRUNDFOS Mexico  
 Boulevard TLC No. 15  
 Parque Industrial Stiva Aeropuerto  
 C.P. 66600 Apodaca, N.L. Mexico  
 Phone: 011-52-81-8144 4000  
 Fax: 011-52-81-8144 4010

www.grundfos.us

