



## GRUNDFOS UNILIFT

### – Domestic wastewater solutions

**UNILIFT KP** is the preferred choice for your drainage needs: removal of grey water, agriculture applications, and more. It can also provide the pumping power to lift water, such as with waterfalls.

- Stainless steel materials
- Hermetically sealed stator
- Pumps up to 10mm solids
- Field replaceable power cords

**UNILIFT CC** is a low-suction drainage pump that features both lightness and strength, from low-lying points of buildings to surface water pits.

- Non-return valve with flexible discharge adaptor
- Built-in venting valve in handle
- Standard 8-ft cable length with built-in float switch
- Removes water to as low as 3mm




## UNILIFT KP

Elegant in design  
Proven in usage



### Performance Curve:

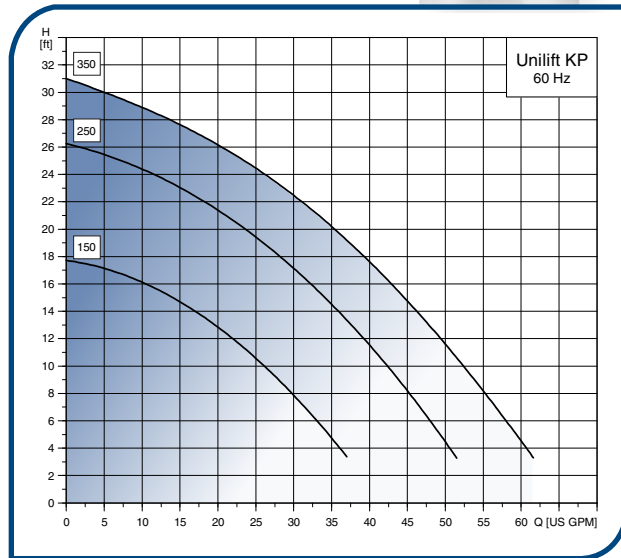


Pump Type	Volts	Material #
<b>10 Foot Cable Length</b>		
Unilift KP 150 - M1	115	011DC001
Unilift KP 150 - A1	115	96847184
Unilift KP 250 - M1	115	012DC001
Unilift KP 250 - A1	115	96847186
Unilift KP 350 - M1	115	013DC001
Unilift KP 350 - A1	115	96847640
<b>25 Foot Cable Length</b>		
Unilift KP 150 - M1	115	011DC201
Unilift KP 150 - A1	115	96847185
Unilift KP 250 - M1	115	012DC201
Unilift KP 250 - A1	115	96847425
Unilift KP 350 - M1	115	013DC201
Unilift KP 350 - A1	115	96847798

## UNILIFT CC

Lightweight, strong and  
multi-purpose



### Performance Curve:

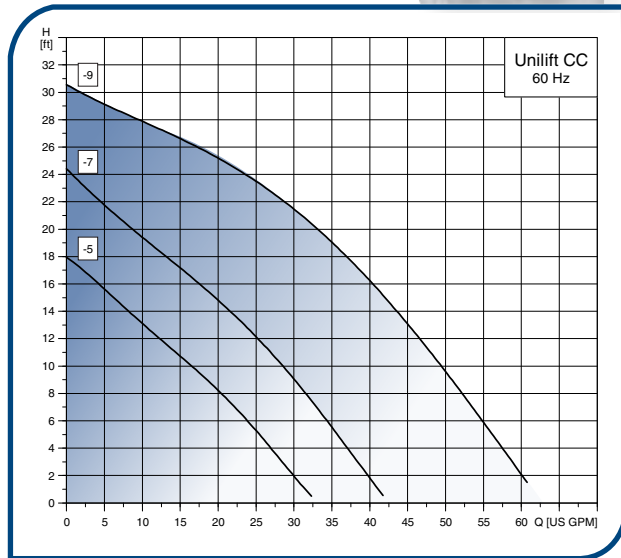

Pump Type	Volts	Material #
Unilift CC 5 - M1	115	96780906
Unilift CC 5 - A1	115	96781199
Unilift CC 7 - M1	115	96781212
Unilift CC 7 - A1	115	96781220
Unilift CC 9 - M1	115	96781221
Unilift CC 9 - A1	115	96781223
Unilift CC 5 - M1	230	96781224
Unilift CC 5 - A1	230	96781225
Unilift CC 7 - M1	230	96781229
Unilift CC 7 - A1	230	96781230
Unilift CC 9 - M1	230	96781231
Unilift CC 9 - A1	230	96781233

L-DWW-SL-02 5/09 (US)